

## DAMPER HINGE HG-JH



INSTRUCTION



- Hinge with built-in dampers hinge UDH 1.
- Smooth movement in the opening direction.
- Left-handed...Damper works when rotating counterclockwise.
- Right-handed...Damper works when rotating clockwise.
- AS parts set for installing to aluminium frame also available. 2

## [Applications]

- Top-opening lids and upper covers of various cabinets.

## [Remarks]



- Be sure to read the "Cautions" 3.
- Torque range is the value when using two hinges for one door.
- Install a stopper such as a stay at the lid opening/closing position (0~115 degree or less) for not exceeding the specified rotation range.
- When installing, ensure that both hinge shafts are levelled and aligned.
- Sold in pairs.

## Selection Tool





Sasuga-kun

## [Installation]

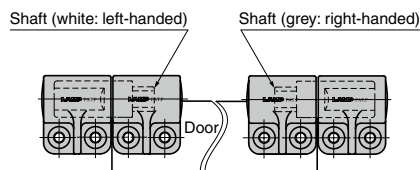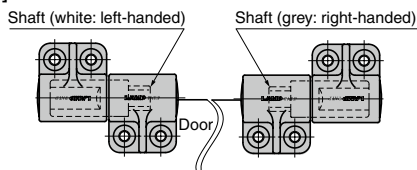

When viewing door from lower side as shown above, install the left-handed type damper (white) on the left side and the right-handed type (grey) on the right side.

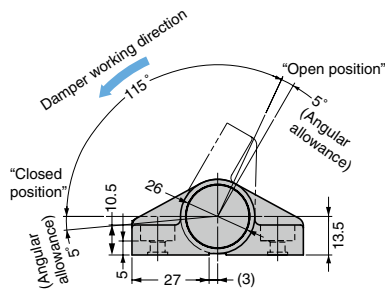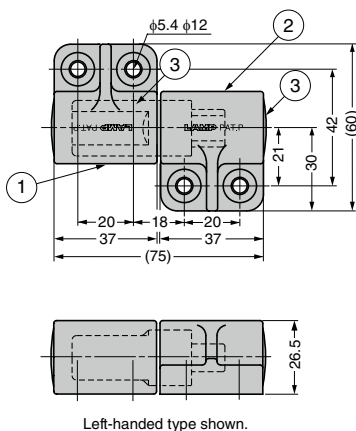

No.	Part Name	Material	Finish / Colour
①	Bracket	PBT	Emboss/Dark Grey
②	Damper		
③	Cap	PP	

RefS	CAD	Item Code	Item Name	Torque N·m/pair	Torque kgf·cm/pair	Marking Colour (Base Side)	Weight (g)	Box (pairs)	Carton (pairs)
G	3D	170-092-209	HG-JH25	3~5	30.6~51	Blue	200	4	64
G	3D	170-092-210	HG-JH35	5~7	51~71.4	Red	193	4	64

Refer to 1 : P.115, 2 : P.97, 3 : P.43