


DETENT HINGE HG-CSH63 With Damper

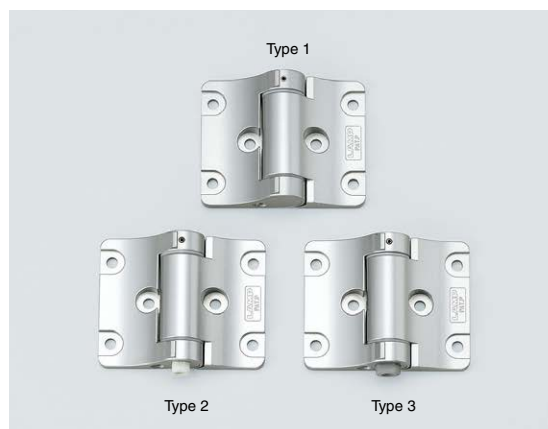

- Detent at both 0° and 100°.
- Also available without damper type.
- Damper works clockwise or counterclockwise.

[Applications]

- Carrying box of motorcycle courier, etc.

[Remarks]

- Be sure to read the "Cautions" .
- When installing, ensure that both hinge shafts are levelled and aligned.
- Torque not adjustable.

TORQUE
HINGES

DAMPER
HINGES

LIFT
ASSIST
HINGES

DETENT
HINGES

CONCEALED
HINGES

BUTT
HINGES

PIANO
HINGES

STEP
HINGES

LIFT-
OFF
HINGES

PIVOT
HINGES

SPRING
HINGES

CLEAN
ROOM
HINGES


HINGES FOR
ALUMINIUM
FRAME

DROP
HINGES


GLASS
DOOR
HINGES

SPECIAL
HINGES

[Installation]

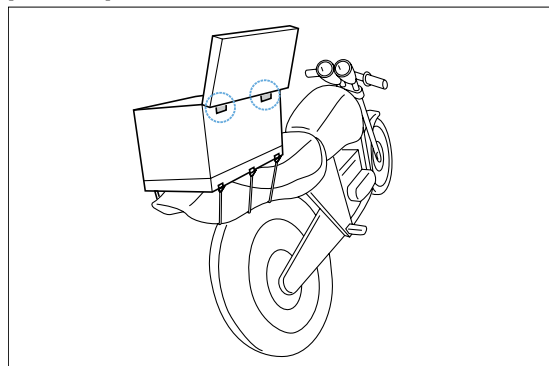

[Installation]

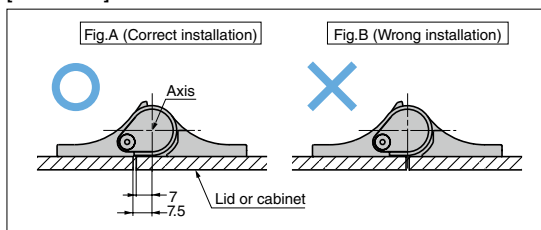



As shown in Fig. A, shift the axis of hinge and the edge of lid or cabinet.

Selection Tool



Sasuga-kun

[Types]

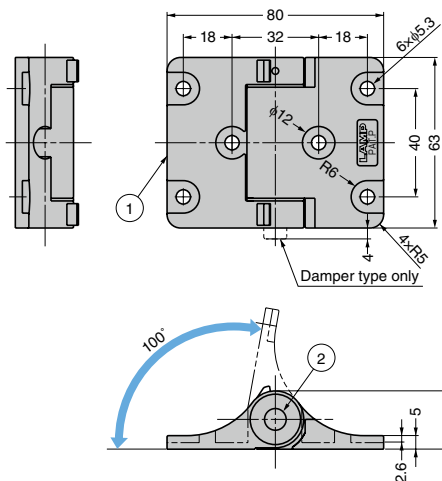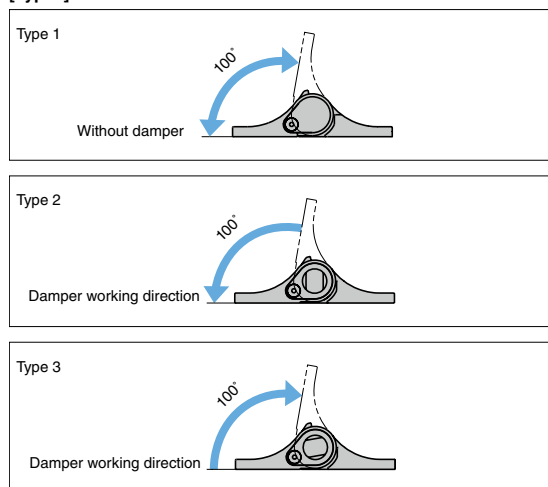

No.	Part Name	Material	Finish / Colour
①	Body	Aluminium Alloy	Silver Enamel Finish
②	Shaft · Spring	Stainless Steel (SUS304)	—

RoHS	CAD	Item Code	Item Name	Type	Torque N·m/pc	Torque kgf·cm/pc	Retaining Torque N·m/pc	Retaining Torque kgf·cm/pc	Opening Angle	Weight (g)	Box (pcs)	Carton (pcs)
—		170-090-044	HG-CSH63	1 (Without Damper)	—	—	0.98	10	100°	98.7	10	120
		170-090-109	HG-CSH63AM	2	1~1.7	10.2~17.3					10	120
		170-090-108	HG-CSH63AH		1.7~2.5	17.3~25.5					10	120
		170-090-111	HG-CSH63BM	3	1~1.7	10.2~17.3					10	120
		170-090-110	HG-CSH63BH		1.7~2.5	17.3~25.5					10	120

Refer to  : P.43