


CONCEALED HINGE RK-50

SUS

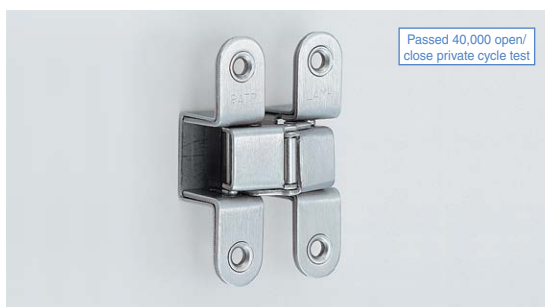


- High corrosion with stainless steel.
- For light door.

[Remarks]


- When increasing the board thickness, be sure to keep the dimensions of ※ marked on below drawings and increase the remaining margins on the opposite side.
- Recommended for use in pairs.

[Parts Included]

- Countersunk head wood screw 2.4×13 (SUS)

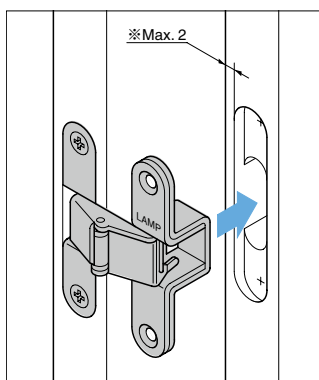

※ Distance to door edge must be less than 2mm.

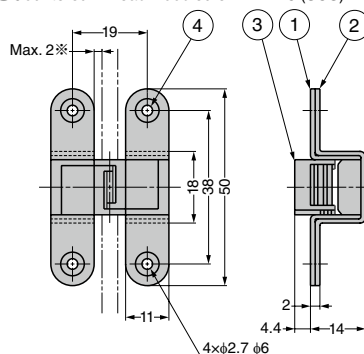

No.	Part Name	Material	Finish
①	Body	Stainless Steel (SUS304)	Satin
②	Cover		Plain
③	Arm		Satin
④	Eyelet		Plain
-	Other Shaft Parts		

RHS	CAD	Item Code	Item Name	Door Width	Door Height	Door Thickness	Door Weight kg/2 pcs	Opening Angle	Weight (g)	Box (pcs)	Carton (pcs)
		170-090-086	RK-50	Max. 450	Max. 700	Min. 15	Max. 2.6	180°	28	24	240

TORQUE HINGES

DAMPER HINGES

LIFT ASSIST HINGES

DETENT HINGES

CONCEALED HINGES

BUTT HINGES

PIANO HINGES

STEP HINGES

LIFT-OFF HINGES

PIVOT HINGES

SPRING HINGES

CLEAN ROOM HINGES

HINGES FOR ALUMINIUM FRAME

DROP HINGES

GLASS DOOR HINGES

SPECIAL HINGES

CONCEALED HINGE INO-66N



- Stainless steel front plate.

[Applications]

- Folding door or window, door of built-in furniture, etc.



[Remarks]

- When using three hinges, install the middle one 200mm below the upper hinge.
- ※ Distance to door edge must be less than 4mm.


[Recommended Screws]

- Countersunk head wood screw 5.8

[Installation]

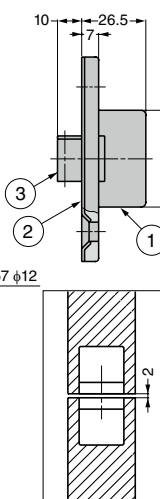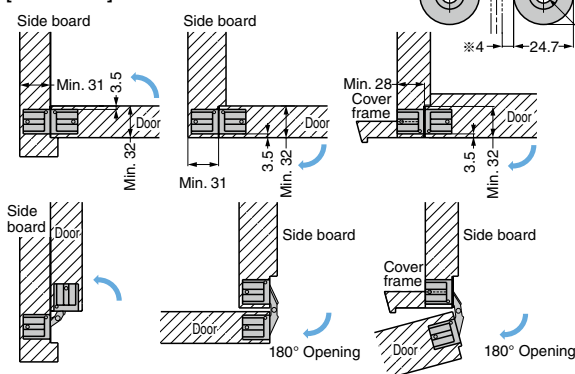

[Cut out dimensions]

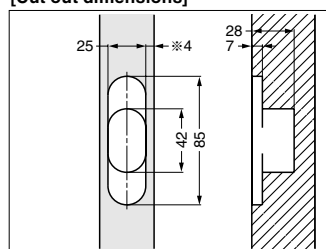

No.	Part Name	Material	Finish
①	Body	PA	-
②	Front Plate	Stainless Steel (SUS304)	Satin
③	Arm		-

RHS	CAD	Item Code	Item Name	Door Width	Door Height	Door Weight kg/2 pcs	Door Weight kg/3 pcs	Opening Angle	Weight (g)	Box (pcs)	Carton (pcs)
		170-095-018	INO-66N	Max. 800	Max. 2100	Max. 30	Max. 50	180°	100	24	144