


BUTT HINGE **KHA**

SUS

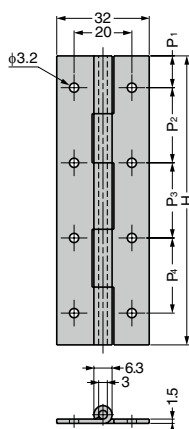

- Various sizes available.
- Steel hinge also available on order. For further details, please contact local representatives.

[Remarks]

- Load capacity is the value when using two hinges. For calculation conditions, please refer to INDEX **1**.


Material	Finish
Stainless Steel (SUS304)	Polished

TORQUE
HINGESDAMPER
HINGESLIFT
ASSIST
HINGESDETENT
HINGESCONCEALED
HINGESBUTT
HINGESPIANO
HINGESSTEP
HINGESLIFT-
OFF
HINGESPIVOT
HINGESSPRING
HINGESCLEAN
ROOM
HINGESHINGES FOR
ALUMINIUM
FRAMEDROP
HINGESGLASS
DOOR
HINGESSPECIAL
HINGES**[With Mounting Holes]**

RoHS	CAD	Item Code	Item Name	H	P ₁	P ₂	P ₃	P ₄	Knuckles	Load Capacity N/2 pcs	Load Capacity kgf/2 pcs	Weight (g)	Box (pcs)	Carton (pcs)
✓	3D	170-091-180	KHA-25C	25	6	13	-	-	3	49	5	13	200	800
✓	3D	170-091-181	KHA-30C	30	7	16	-	-	3	59	6	16	200	800
✓	3D	170-091-182	KHA-40C	40	8	24	-	-	3	69	7	21	150	600
✓	3D	170-091-183	KHA-50C	50	10	30	-	-	3	88	9	26	100	400
✓	3D	170-091-184	KHA-60C	60	8	22	22	-	5	108	11	31	100	400
✓	3D	170-091-185	KHA-65C	65	8.5	24	24	-	5	118	12	34	100	400
✓	3D	170-091-186	KHA-75C	75	9.5	28	28	-	5	137	14	39	50	200
✓	3D	170-091-187	KHA-80C	80	10	30	30	-	5	147	15	42	50	200
✓	3D	170-091-188	KHA-90C	90	11	35	35	-	5	167	17	47	50	200
✓	3D	170-091-189	KHA-100C	100	11	26	26	26	5	186	19	52	50	200

Refer to **1** : P.43**[Without Mounting Holes]**

RoHS	CAD	Item Code	Item Name	H	Knuckles	Load Capacity N/2 pcs	Load Capacity kgf/2 pcs	Weight (g)	Box (pcs)	Carton (pcs)
✓	3D	170-091-170	KHA-25CN	25	3	49	5	13	200	800
✓	3D	170-091-171	KHA-30CN	30	3	59	6	16	200	800
✓	3D	200-091-172	KHA-40CN	40	3	69	7	21	150	600
✓	3D	170-091-191	KHA-50CN	50	3	88	9	26	100	400
✓	3D	170-091-192	KHA-60CN	60	5	108	11	31	100	400
✓	3D	170-091-193	KHA-65CN	65	5	118	12	34	100	400
✓	3D	170-091-194	KHA-75CN	75	5	137	14	39	50	200
✓	3D	170-091-195	KHA-80CN	80	5	147	15	42	50	200
✓	3D	170-091-196	KHA-90CN	90	5	167	17	47	50	200
✓	3D	170-091-179	KHA-100CN	100	5	186	19	52	50	200

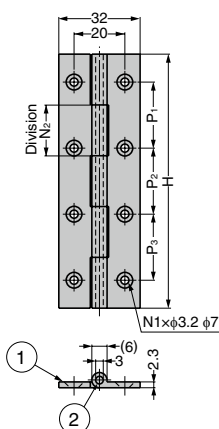BUTT HINGE **KHB**

- Drawing material, with small shaft diameter.
- Various sizes available.

[Applications]

- Ship, vehicle, kitchen equipment

[Remarks]

- Load capacity is the value when using two hinges. For calculation conditions, please refer to INDEX **1**.

No.	Part Name	Material	Finish
①	Body	Brass	Chrome
②	Shaft		-

RoHS	CAD	Item Code	Item Name	H	P ₁	P ₂	P ₃	N ₁	N ₂	Load Capacity N/2 pcs	Load Capacity kgf/2 pcs	Weight (g)	Box (pcs)	Carton (pcs)
✓	3D	170-091-226	KHB-25CR	25	13	-	-	4	3	49	5	17	200	800
✓	3D	170-091-227	KHB-30CR	30	16	-	-	4	3	59	6	20	150	600
✓	3D	170-091-228	KHB-40CR	40	24	-	-	4	3	78	8	28	100	400
✓	3D	170-091-229	KHB-50CR	50	30	-	-	4	3	98	10	35	100	400
✓	3D	170-091-230	KHB-60CR	60	22	22	-	6	5	118	12	41	60	240
✓	3D	170-091-231	KHB-65CR	65	24	24	-	6	5	127	13	43	60	240
✓	3D	170-091-232	KHB-75CR	75	28	28	-	6	5	147	15	52	60	240
✓	3D	170-091-233	KHB-80CR	80	30	30	-	6	5	157	16	54	60	240
✓	3D	170-091-234	KHB-90CR	90	35	35	-	6	5	177	18	63	50	200
✓	3D	170-091-235	KHB-100CR	100	26	26	26	8	5	206	21	68	50	200

Refer to **1** : P.43