


## TABLETOP HINGE MH-30



- Double pivot hinge allows 180° opening.

### [Remarks]

- Recommended door dimensions in the table below are the value when using two hinges for one door.
- Load capacity is the value when using two hinges. For calculation conditions, please refer to INDEX 1D.

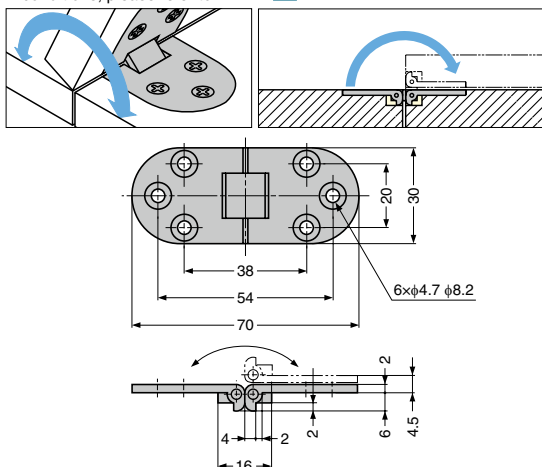

| RoHS | CAD | Item Code   | Item Name | Material | Finish               | Door Width  | Door Height | Door Thickness | Load Capacity<br>N/2 pcs | Load Capacity<br>kgf/2 pcs | Opening Angle | Weight (g) | Box (pcs) | Carton (pcs) |
|------|-----|-------------|-----------|----------|----------------------|-------------|-------------|----------------|--------------------------|----------------------------|---------------|------------|-----------|--------------|
| —    | 3D  | 170-090-052 | MH-30M    | Brass    | Polished             | Max.<br>450 | Max.<br>700 | Max.<br>21     | 29                       | 3                          | 180°          | 45         | 24        | 360          |
| —    | 3D  | 170-090-051 | MH-30WB   |          | White Bronze Plating |             |             |                |                          |                            |               |            | 24        | 360          |
| —    | 3D  | 170-090-050 | MH-30CR   |          | Chrom                |             |             |                |                          |                            |               |            | 24        | 360          |

Refer to 1D : P.43


## TABLETOP HINGE MH-40



- Double pivot hinge allows 180° opening.

### [Remarks]

- Recommended door dimensions in the table below are the value when using two hinges for one door.
- Load capacity is the value when using two hinges. For calculation conditions, please refer to INDEX 1D.

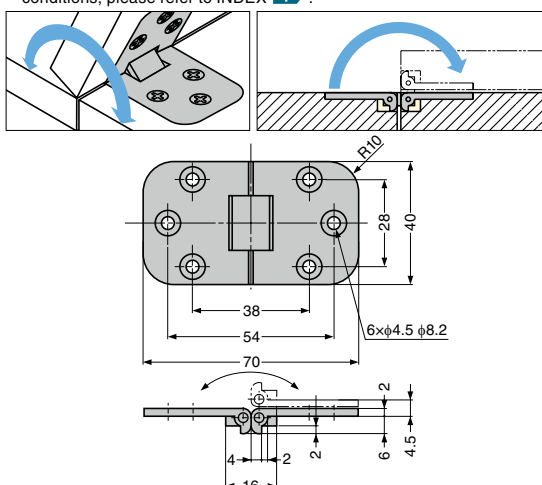

| RoHS | CAD | Item Code   | Item Name | Material | Finish               | Door Width  | Door Height | Door Thickness | Load Capacity<br>N/2 pcs | Load Capacity<br>kgf/2 pcs | Opening Angle | Weight (g) | Box (pcs) | Carton (pcs) |
|------|-----|-------------|-----------|----------|----------------------|-------------|-------------|----------------|--------------------------|----------------------------|---------------|------------|-----------|--------------|
| —    | 3D  | 170-090-057 | MH-40M    | Brass    | Polished             | Max.<br>450 | Max.<br>700 | Max.<br>21     | 29                       | 3                          | 180°          | 64         | 16        | 240          |
| —    | 3D  | 170-090-056 | MH-40WB   |          | White Bronze Plating |             |             |                |                          |                            |               |            | 16        | 240          |
| —    | 3D  | 170-090-055 | MH-40CR   |          | Chrom                |             |             |                |                          |                            |               |            | 16        | 240          |

Refer to 1D : P.43