


MINI LID STAY (W/ LOCK) L-FS140 Slide release

TEST
METHOD 16


L=R

SUS

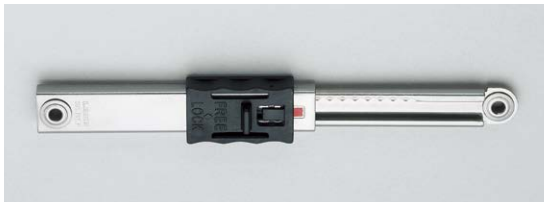


[Installation]

Without bracket

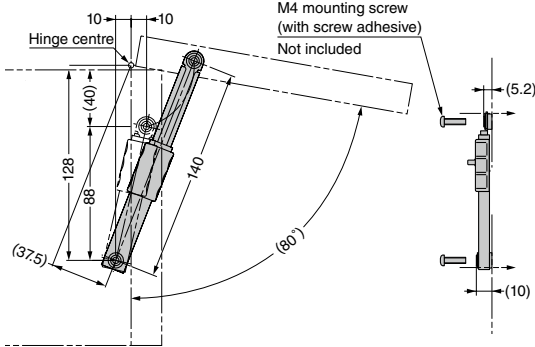

With bracket

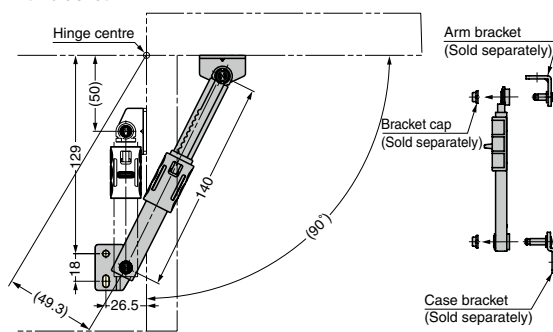

Opening Direction	Description	Non-handed	Qty	Compression Load
 Top-opening	Multi-angle Lock	Yes	1 Pc Per Door 2 Pcs Per Door	58.8 N/pc (6 kgf/pc)
 Upward-opening				
 Swing Door				


- Locks the lid at multiple angles.
Sliding the lock lever in any position simultaneously locks the extension direction and compression direction.
- Installation pitch is identical to L-140S **1**.
- Plastic parts and metal parts can be separated.

[Remarks]


- Do not use this product as a stopper.
- Allow room for stroke when installing.
- Securely fix the mounting screws with screw adhesive.
- Opening angle and installation position change depending on the position of hinge centre. Determine the installation position based on the hinges used and cabinet shape.
- For wooden door, use BRACKET L-FS140-BT (sold separately) **2**.
- Calculate suitable door size with reference to LID STAY SERIES **3**.

[Sold Separately]

- Mounting bracket L-FS140-BT **2**

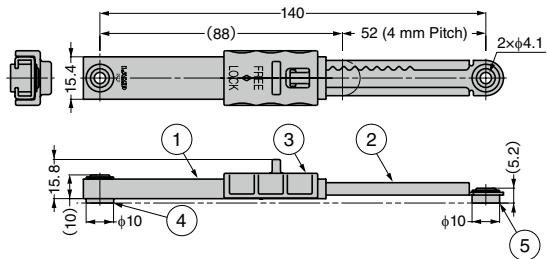

[Lock and Release]

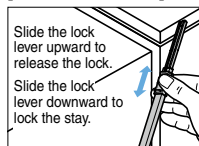


No.	Part Name	Material	Finish/Colour
①	Body	Stainless Steel (SUS304)	Barrel Polished
②	Arm		
③	Lock Lever	POM	Dark Grey
④	Case Bracket	Stainless Steel (SUS304)	-
⑤	Arm Bracket		

RHS	CAD	Item Code	Item Name	Compression Load N/pc	Compression Load kgf/pc	Weight (g)	Box (pcs)	Carton (pcs)
		180-100-108	L-FS140	58.8	6	50	20	200

Refer to **1** : P.414, **2** : P.412, **3** : P.399

BRACKET L-FS140-BT For L-FS140

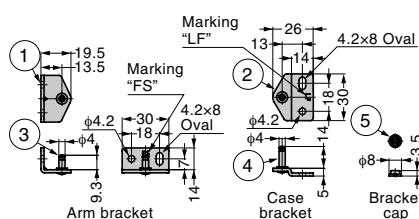

- Bracket for L-FS140 **1**.
- One-touch installation with the bracket cap.
- Refer to the stay page **1** for installation details.

[Remarks]

- For L-FS140 only.
- Do not apply excessive force in the direction of removing the cap.

RHS	CAD	Item Code	Item Name	Weight (g)	Box (sets)	Carton (sets)
		180-028-720	L-FS140-BT	27	40	400

Refer to **1** : P.412

No.	Part Name	Material	Finish/Colour
①	Arm Bracket	Stainless Steel (SUS304)	Barrel Polished
②	Case Bracket		
③	Shaft of Arm Bracket	Stainless Steel (SUS303)	Plain
④	Shaft of Case Bracket		
⑤	Bracket Cap	POM	Black