

# FULL EXTENSION SLIDE SNS27D

LOAD CAPACITY

275~373 N/pair


L=R

SUS




- Full extension (3 members).

### [Remarks]

- Be sure to read the "Cautions" .





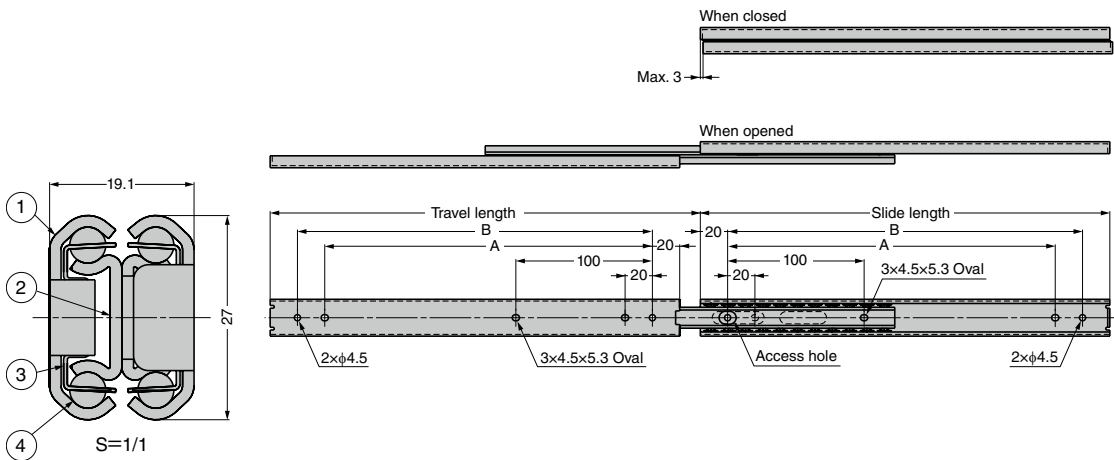








 
### [Recommended Screws]

- M4 pan head screw or nominal 4 pan head tapping screw



No.	Part Name	Material	Finish
①	Outer Member	Stainless Steel (SUS304)	Plain
②	Inner Member		
③	Retainer		
④	Balls	Stainless Steel (SUS440)	-

Sold by piece.

RHS	CAD	Item Code	Item Name	Slide Length	Travel Length	A	B	Load Capacity N/pair	Load Capacity kgf/pair	Weight (kg/pc)	Box (pcs)	Carton (pcs)
		190-110-184	SNS27D-20	200	216.8	140	160	373	38	0.34	20	-
		190-110-185	SNS27D-25	250	266	190	210	363	37	0.42	20	-
		190-110-186	SNS27D-30	300	315.2	240	260	353	36	0.50	20	-
		190-110-187	SNS27D-35	350	364.4	290	310	333	34	0.58	20	-
		190-110-188	SNS27D-40	400	413.6	340	360	313	32	0.66	20	-
		190-110-189	SNS27D-45	450	462.8	390	410	294	30	0.74	20	-
		190-110-190	SNS27D-50	500	512	440	460	275	28	0.82	20	-

Refer to  : P.549