


3/4 EXTENSION SLIDE AR2-K With Hold-out Detent**LOAD CAPACITY** 85~125 N/pair**HOLD OPENED****L=R**

- 3/4 extension (2 members).
- The drawer can be held in fully opened position.
- Small size and light weight.

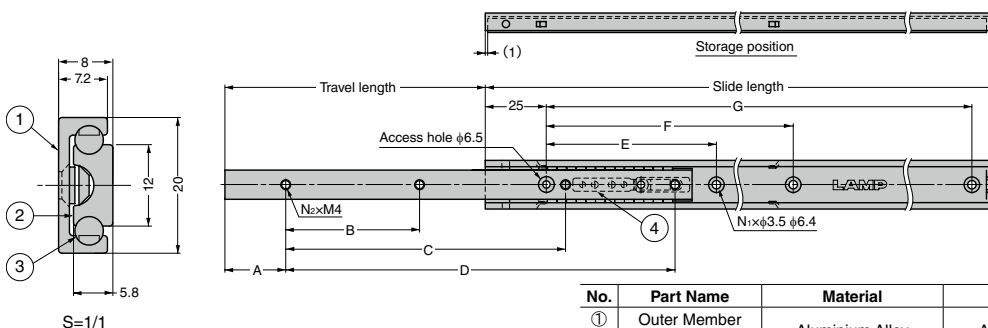

No.	Part Name	Material	Finish
①	Outer Member	Aluminium Alloy	Anodised Silver
②	Inner Member		
③	Balls	Steel (SWCH)	-
④	Detent Catch	Stainless Steel (SUS304)	


Sold by piece.

RoHS	CAD	Item Code	Item Name	Slide Length	Travel Length	A	B	C	D	E	F	G	N ₁	N ₂	Load Capacity N/pair	Load Capacity kgf/pair	Weight (g/pc)	Box (pcs)	Carton (pcs)
✓	3D	190-112-251	AR2-K200	200	110	25	60	160	-	150	-	-	2	3	125	12.7	64	500	-
✓	3D	190-112-252	AR2-K300	300	170	-	100	230	-	-	250	-	3	-	110	11.2	97	250	-
✓	3D	190-112-253	AR2-K400	400	230	45	150	270	330	130	-	350	-	4	95	9.7	130	200	-
✓	3D	190-112-254	AR2-K500	500	290	-	190	340	430	-	280	450	-	-	85	8.7	162	200	-

*When current stock runs out, the box quantity will be changed.

FULL EXTENSION SLIDE AR3-K With Hold-out Detent**LOAD CAPACITY** 85~105 N/pair**HOLD OPENED****L=R**

- Full extension (3 members).
- The drawer can be held in fully opened position.
- Small size and light weight.

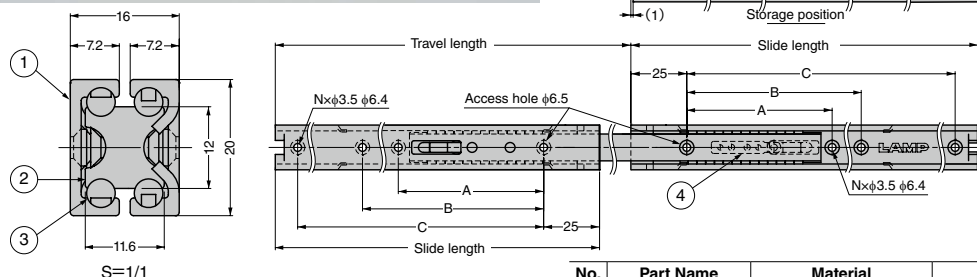

No.	Part Name	Material	Finish
①	Outer Member	Aluminium Alloy	Anodised Silver
②	Inner Member		
③	Balls	Steel (SWCH)	-
④	Detent Catch	Stainless Steel (SUS304)	

Sold by piece.

RoHS	CAD	Item Code	Item Name	Slide Length	Travel Length	A	B	C	N	Load Capacity N/pair	Load Capacity kgf/pair	Weight (g/pc)	Box (pcs)	Carton (pcs)
✓	3D	190-112-255	AR3-K200	200	214	150	-	-	2	105	10.7	130	250	-
✓	3D	190-112-256	AR3-K300	300	314	-	250	-	3	100	10.2	198	125	-
✓	3D	190-112-257	AR3-K400	400	414	130	280	350	4	90	9.2	263	100	-
✓	3D	190-112-258	AR3-K500	500	514	-	-	450	-	85	8.7	304	100	-

*When current stock runs out, the box quantity will be changed.