

ALUMINIUM DOOR HANDLE SRH Antibacterial Type

TEST
METHOD 20


ANTIBACTERIAL




- Sleek handle with flowing curve design.
- Designed to protrude only a small amount.
- Has anti-bacterial coating.

[Applications]


- Medical and diagnostic equipment.

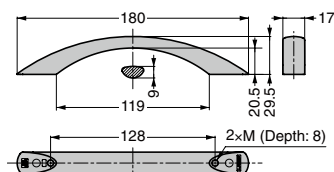

SRH-128

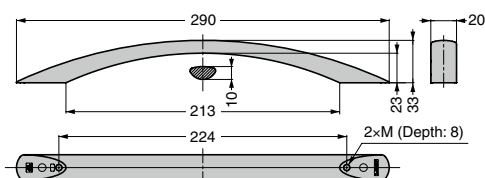

SRH-224

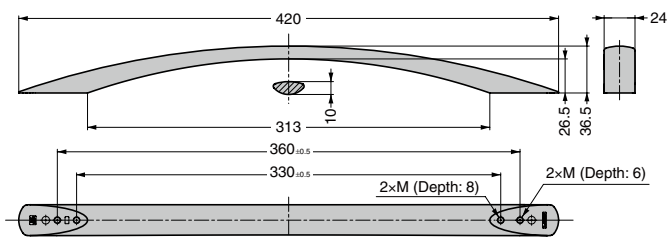

SRH-330

RoHS	CAD	Item Code	Item Name	Material	Finish/Colour	M	Load Capacity		Weight (g)	Box (pcs)	Carton (pcs)
							N	kgf			
✓	3D	100-044-288	SRH-128SL-M4	Aluminium Alloy (ADC)	Silver Enamel Finish	4	500	51	68	10	80
✓	3D	100-044-289	SRH-128SL-M5		Silver Enamel Finish	5				10	80
✓	3D	100-044-290	SRH-128BL-M4		Matt Black Enamel Finish	4				10	80
✓	3D	100-044-291	SRH-128BL-M5		Matt Black Enamel Finish	5				10	80
✓	3D	100-044-292	SRH-224SL-M4		Silver Enamel Finish	4	500	51	130	10	80
✓	3D	100-044-293	SRH-224SL-M5		Silver Enamel Finish	5				10	80
✓	3D	100-044-294	SRH-224BL-M4		Matt Black Enamel Finish	4				10	80
✓	3D	100-044-295	SRH-224BL-M5		Matt Black Enamel Finish	5				10	80
✓	3D	100-044-296	SRH-330SL-M4		Silver Enamel Finish	4	400	41	233	10	40
✓	3D	100-044-297	SRH-330SL-M5		Silver Enamel Finish	5				10	40
✓	3D	100-044-298	SRH-330BL-M4		Matt Black Enamel Finish	4				10	40
✓	3D	100-044-299	SRH-330BL-M5		Matt Black Enamel Finish	5				10	40