


STAINLESS STEEL HANDLE FT-S280 Large Type

NSF SUS316

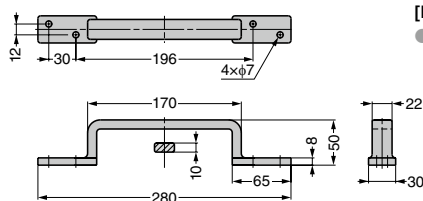

[Parts Included]

- Binding head tapping screw 6×35 (SUS)


RoHS	CAD	Item Code	Item Name	Material	Finish	Weight (g)	Box (pcs)	Carton (pcs)
		100-010-071	FT-S280	Stainless Steel (SCS14)	Polished	612	1	20

※ Limited stock available. Please contact your local agent or your nearest Sugatsune subsidiary for detail/availability.

※ SCS14 is equivalent to SUS316.

STAINLESS STEEL HANDLE FT Large Type

NSF SUS316

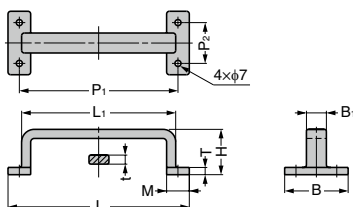

[Parts Included]

- Binding head tapping screw 6×35 (SUS)

RoHS	CAD	Item Code	Item Name	Material	Finish	L	L1	B	B1	H	T	t	M	P1	P2	Weight (g)	Box (pcs)	Carton (pcs)
		100-010-069	FT-200	Stainless Steel (SCS14)	Polished	200	170	70	22	50	8	10	25	175	45	586	1	20
		100-010-070	FT-280	Stainless Steel (SCS14)	Polished	280	250	80	26	62	10	12	27	253	55	1088	1	10

※ SCS14 is equivalent to SUS316.

HANDLE (STAINLESS, TITANIUM) 2LC

NSF TITANIUM SUS316




- Easy to grab.
- 2 types of materials available: Light weight and strong titanium with excellent corrosion resistance, and cast steel SCS14 equivalent to stainless steel SUS316.
- Titanium handle hardly causes metal allergy. In addition, since it is non-magnetic, suitable for medical devices such as MRI.

[Remarks]

- Screws are not included for titanium handles.

[Parts Included]

- For only stainless handle: Pan head tapping screw (SUS)

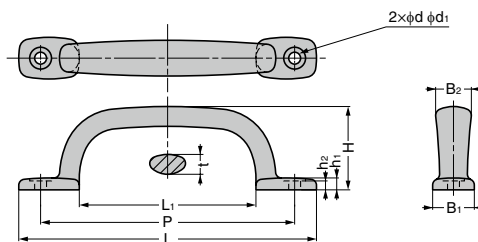

RoHS	CAD	Item Code	Item Name	Material	Finish	L	L1	P	B1	B2	H	h1	h2	t	d	d1	Weight (g)	Included Screws	Recommended Screws	Box (pcs)	Carton (pcs)
-		100-010-355	2LC-80TI	Titanium	Shot Blast	80	32	64	16	14	35	5.5	4	8	5	9.5	37	-	M4	30	144
-		100-010-354	2LC-120TI			120	64	96	18	16	36	5.5	4	9	5	9.5	62			20	96
-		100-010-353	2LC-150TI			150	89	128	21	18	42	6	4.5	10	6	11	96			6	72
		100-010-131	2LC-80	Stainless Steel (SCS14)	Polished	80	32	64	16	14	35	5.5	4	8	5	9.5	70	4×20	M4	12	144
		100-010-132	2LC-120			120	64	96	18	16	36	5.5	4	9	5	9.5	106			8	96
		100-010-133	2LC-150			150	89	128	21	18	42	6	4.5	10	6	11	172	5×30	M5	6	72
		100-010-134	2LC-180			180	118	160	23	20	45	6.5	5	10	6	11	225			3	36

※ SCS14 is equivalent to SUS316.