


## STAINLESS STEEL HANDLE EC-H

SUS

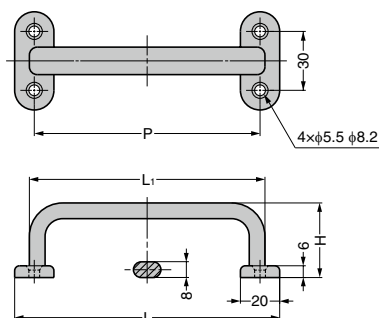


## [Parts Included]

- Raised countersunk head tapping screw 4×20 (SUS)

| RoHS | CAD | Item Code   | Item Name | Material                 | Finish   | L   | L <sub>1</sub> | H  | P   | Weight (g) | Box (pcs) | Carton (pcs) |
|------|-----|-------------|-----------|--------------------------|----------|-----|----------------|----|-----|------------|-----------|--------------|
|      |     | 100-010-056 | EC-H-135  | Stainless Steel (SUS303) | Polished | 135 | 120            | 40 | 115 | 191        | 5         | 50           |
|      |     | 100-010-057 | EC-H-165  |                          |          | 165 | 150            | 42 | 145 | 216        | 3         | 48           |

## STAINLESS STEEL HANDLE FT Double-hole Type

NSF SUS

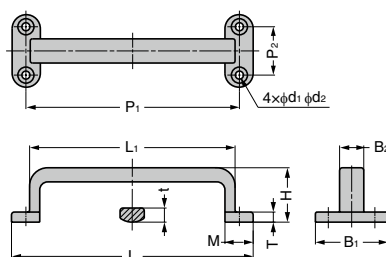

## [Parts Included]


- FT-120: Raised countersunk head wood screw (SUS) 3.8×20
- FT-150: Raised countersunk head wood screw (SUS) 5.1×25

| RoHS | CAD | Item Code   | Item Name | Material                | Finish   | L   | L <sub>1</sub> | B <sub>1</sub> | B <sub>2</sub> | H  | T | t | M  | P <sub>1</sub> | P <sub>2</sub> | d <sub>1</sub> | d <sub>2</sub> | Weight (g) | Box (pcs) | Carton (pcs) |
|------|-----|-------------|-----------|-------------------------|----------|-----|----------------|----------------|----------------|----|---|---|----|----------------|----------------|----------------|----------------|------------|-----------|--------------|
|      |     | 100-010-067 | FT-120    | Stainless Steel (SCS13) | Polished | 120 | 102            | 36             | 12             | 27 | 5 | 7 | 14 | 106            | 24             | 4.1            | 8              | 105        | 10        | 120          |
|      |     | 100-010-068 | FT-150    |                         |          | 150 | 129            | 45             | 15             | 33 | 6 | 8 | 18 | 132            | 30             | 5.3            | 10.4           | 191        | 5         | 40           |

※SCS13 is equivalent to SUS304.

## STAINLESS STEEL HANDLE FT Single-hole Type

NSF SUS

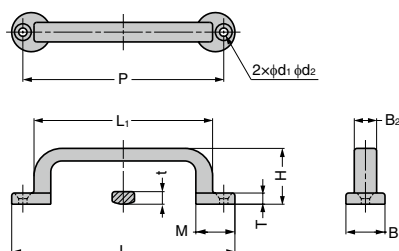

## [Parts Included]

- FT-65, FT-80: Raised countersunk head wood screw (SUS) 3.1×16
- FT-100: Raised countersunk head wood screw (SUS) 3.8×20

| RoHS | CAD | Item Code   | Item Name | Material                | Finish   | L   | L <sub>1</sub> | B <sub>1</sub> | B <sub>2</sub> | H  | T   | t   | M  | P  | d <sub>1</sub> | d <sub>2</sub> | Weight (g) | Box (pcs) | Carton (pcs) |
|------|-----|-------------|-----------|-------------------------|----------|-----|----------------|----------------|----------------|----|-----|-----|----|----|----------------|----------------|------------|-----------|--------------|
|      |     | 100-012-847 | FT-65     | Stainless Steel (SCS13) | Polished | 65  | 47             | 13             | 7              | 16 | 3.5 | 4   | 13 | 57 | 3.3            | 6.4            | 19         | 40        | 480          |
|      |     | 100-012-848 | FT-80     |                         |          | 80  | 61             | 14             | 8              | 20 | 4   | 4.5 | 14 | 72 |                |                | 32         | 30        | 360          |
|      |     | 100-012-849 | FT-100    |                         |          | 100 | 75             | 18             | 10             | 25 | 5   | 5.5 | 18 | 88 |                |                | 58         | 20        | 240          |

※SCS13 is equivalent to SUS304.