

## HANDLE KMH


TEST  
METHOD 1

※Caps are sold separately.

## [Caps] Option



## [Without Cap]

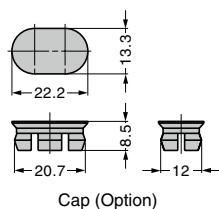

Cap (Option)

Video Link



- Cap hides screw heads for clean appearance (option). 4 colours available.
- Stylish flat surface.
- Rounded inside allows for easy gripping.
- Caps are tightly fixed to prevent from falling off.
- Possible to customise cap colour from 10,000 pcs.



## [Remarks]

- Truss head screws can not be used.
- Caps are sold separately. Sold by piece. Please order together with handle.

## [Recommended Screws]

- Hexagon socket head cap screw M5 or Pan head screw M5

## [Installation]

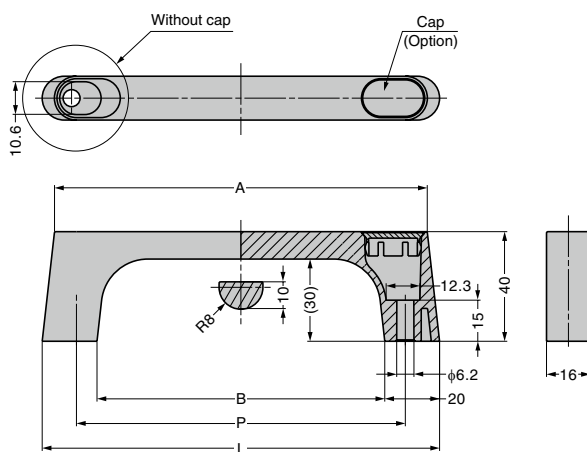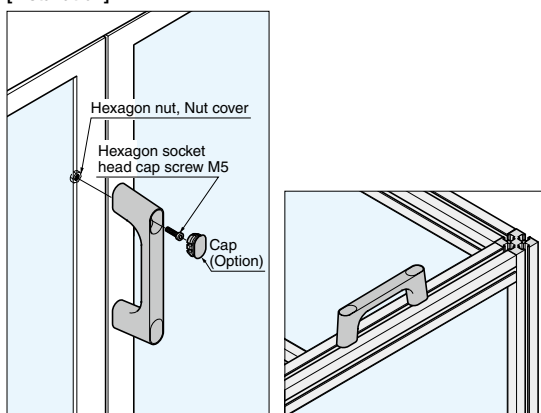

## [Body]

| RoHS | CAD | Item Code   | Item Name | Material         | Finish       | L   | A   | B   | P   | Load Capacity N | Load Capacity kgf | Weight (g) | Box (pcs) | Carton (pcs) |
|------|-----|-------------|-----------|------------------|--------------|-----|-----|-----|-----|-----------------|-------------------|------------|-----------|--------------|
| ✓    | SD  | 100-024-063 | KMH-100   | Zinc Alloy (ZDC) | Satin Chrome | 125 | 116 | 85  | 100 | 500             | 51                | 162        | 10        | 100          |
| ✓    | SD  | 100-024-064 | KMH-120   |                  |              | 145 | 136 | 105 | 120 |                 |                   | 180        | 10        | 60           |
| ✓    | SD  | 100-024-065 | KMH-150   |                  |              | 175 | 166 | 135 | 150 |                 |                   | 206        | 10        | 60           |

## [Caps] Option (Sold by piece)

| RoHS | CAD | Item Code   | Item Name | Material | Colour     | Weight (g) | Box (pcs) | Carton (pcs) |
|------|-----|-------------|-----------|----------|------------|------------|-----------|--------------|
| ✓    | —   | 100-024-066 | KMHC-WT   | PBT      | White      | 0.7        | 100       | 2000         |
| ✓    | —   | 100-024-067 | KMHC-GR   |          | Grey       |            | 100       | 2000         |
| ✓    | —   | 100-024-068 | KMHC-BU   |          | Light Blue |            | 100       | 2000         |
| ✓    | —   | 100-024-924 | KMHC-BL   |          | Black      |            | 100       | 2000         |