


STAINLESS STEEL HANDLE H-35

SUS



[Parts Included]

- Truss head screw M4 × 45

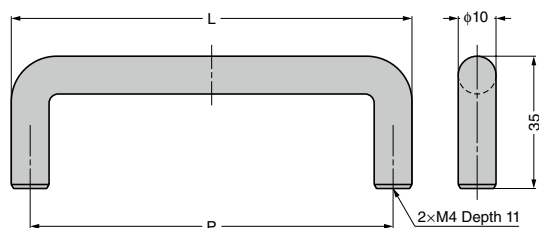

RHS	CAD	Item Code	Item Name	Material	Finish	L	P	Weight (g)	Box (pcs)	Carton (pcs)
		100-036-723	H-35-96-SS	Stainless Steel (SUS304)	Satin	106	96	86	25	—
		100-036-724	H-35-96-SM		Mirror	106	96	86	25	—
		100-036-725	H-35-128-SS		Satin	138	128	106	25	—
		100-036-726	H-35-128-SM		Mirror	138	128	106	25	—
		100-036-727	H-35-160-SS		Satin	170	160	125	25	—
		100-036-728	H-35-160-SM		Mirror	170	160	125	25	—
		100-036-729	H-35-192-SS		Satin	202	192	145	25	—
		100-036-730	H-35-192-SM		Mirror	202	192	145	25	—
		100-036-731	H-35-288-SS		Satin	298	288	204	25	—
		100-036-732	H-35-288-SM		Mirror	298	288	204	25	—


STAINLESS STEEL HANDLE H-29

SUS



[Parts Included]

- Truss head screw M4 × 45

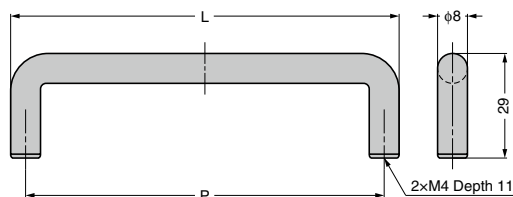

RHS	CAD	Item Code	Item Name	Material	Finish	L	P	Weight (g)	Box (pcs)	Carton (pcs)
		100-036-733	H-29-64-SS	Stainless Steel (SUS304)	Satin	72	64	39	25	—
		100-036-734	H-29-64-SM		Mirror	72	64	39	25	—
		100-036-735	H-29-96-SS		Satin	104	96	52	25	—
		100-036-736	H-29-96-SM		Mirror	104	96	52	25	—
		100-036-737	H-29-128-SS		Satin	136	128	64	25	—
		100-036-738	H-29-128-SM		Mirror	136	128	64	25	—
		100-036-739	H-29-160-SS		Satin	168	160	77	25	—
		100-036-740	H-29-160-SM		Mirror	168	160	77	25	—
		100-036-741	H-29-192-SS		Satin	200	192	90	25	—
		100-036-742	H-29-192-SM		Mirror	200	192	90	25	—