


## STAINLESS STEEL HANDLE XL-CU



● Finish: Combination of polished and satin.

## [Parts Included]

● Truss head screw M5×30 (SUS)

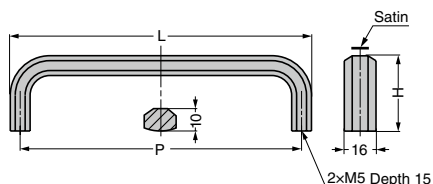

LARGE HANDLES

HANDLES (FRONT SCREW MOUNT)

HANDLES (BACK SCREW MOUNT)

RECESSED PULLS

PULLS & KNOBS

LATCH HANDLES


| RoHS | CAD | Item Code   | Item Name  | Material                 | Finish                         | L   | H  | P   | Weight (g) | Box (pcs) | Carton (pcs) |
|------|-----|-------------|------------|--------------------------|--------------------------------|-----|----|-----|------------|-----------|--------------|
| ✓    | 3D  | 100-010-470 | XL-CU80TT  | Stainless Steel (SUS303) | Polished and Satin Combination | 82  | 32 | 72  | 112        | 10        | 100          |
| ✓    | 3D  | 100-010-471 | XL-CU100TT |                          |                                | 102 | 34 | 92  | 136        | 10        | 100          |
| ✓    | 3D  | 100-010-472 | XL-CU120TT |                          |                                | 122 | 36 | 112 | 163        | 10        | 100          |
| ✓    | 3D  | 100-010-473 | XL-CU150TT |                          |                                | 152 | 38 | 142 | 200        | 8         | 80           |
| ✓    | 3D  | 100-010-474 | XL-CU180TT |                          |                                | 182 | 40 | 172 | 234        | 8         | 80           |
| ✓    | 3D  | 100-010-475 | XL-CU220TT |                          |                                | 222 | 42 | 212 | 282        | 8         | 40           |
| ✓    | 3D  | 100-010-476 | XL-CU300TT |                          |                                | 302 | 44 | 292 | 372        | 6         | 30           |

## STAINLESS STEEL HANDLE FB



## [Parts Included]

● Pan head screw M5×25

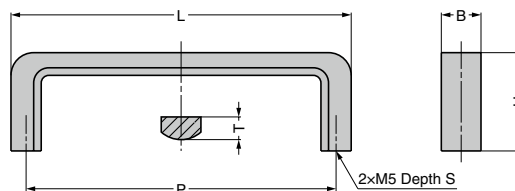

| RoHS | CAD | Item Code   | Item Name | Material                | Finish   | L   | H  | B    | T | P   | S  | Weight (g) | Box (pcs) | Carton (pcs) |
|------|-----|-------------|-----------|-------------------------|----------|-----|----|------|---|-----|----|------------|-----------|--------------|
| ✓    | 3D  | 100-010-074 | FB-90     | Stainless Steel (SCS13) | Polished | 90  | 26 | 10.5 | 6 | 82  | 10 | 45         | 35        | 280          |
| ✓    | 3D  | 100-010-075 | FB-110    |                         |          | 110 | 28 | 12.5 | 7 | 102 | 12 | 60         | 25        | 200          |
| ✓    | 3D  | 100-010-076 | FB-130    |                         |          | 130 | 32 | 14.5 | 8 | 120 | 14 | 93         | 20        | 160          |

※SCS13 is equivalent to SUS304.