


STAINLESS STEEL HANDLE KB



[Parts Included]

- Truss head screw M3×28 (SUS)

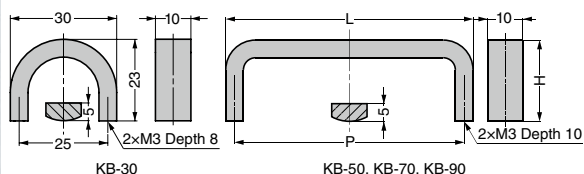

LARGE HANDLES

HANDLES (FRONT SCREW MOUNT)

HANDLES (BACK SCREW MOUNT)

RECESSED PULLS

PULLS & KNOBS

LATCH HANDLES


RoHS	CAD	Item Code	Item Name	Material	Finish	L	H	P	Weight (g)	Box (pcs)	Carton (pcs)
		100-011-094	KB-30S	Stainless Steel (SUS303)	Satin	As Above	As Above	As Above	18	40	400
		100-011-093	KB-30M		Polished	As Above	As Above	As Above	18	40	400
		100-011-096	KB-50S		Satin	50	22	45	26	30	300
		100-011-095	KB-50M		Polished	50	22	45	26	30	300
		100-011-098	KB-70S		Satin	70	22.5	65	33	30	300
		100-011-097	KB-70M		Polished	70	22.5	65	33	30	300
		100-011-100	KB-90S		Satin	90	23	85	40	20	200
		100-011-099	KB-90M		Polished	90	23	85	40	20	200

STAINLESS STEEL HANDLE DS



[Parts Included]

- Truss head screw M3×28 (SUS)

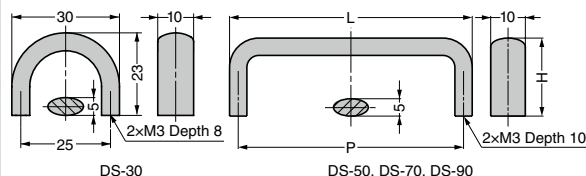


RoHS	CAD	Item Code	Item Name	Material	Finish	L	H	P	Weight (g)	Box (pcs)	Carton (pcs)
		100-011-112	DS-30S	Stainless Steel (SUS303)	Satin	As Above	As Above	As Above	15	40	400
		100-011-111	DS-30M		Polished	As Above	As Above	As Above	15	40	400
		100-011-114	DS-50S		Satin	50	22	45	22	30	300
		100-011-113	DS-50M		Polished	50	22	45	22	30	300
		100-011-116	DS-70S		Satin	70	22.5	65	28	30	300
		100-011-115	DS-70M		Polished	70	22.5	65	28	30	300
		100-011-118	DS-90S		Satin	90	23	85	35	20	200
		100-011-117	DS-90M		Polished	90	23	85	35	20	200

STAINLESS STEEL HANDLE DL



[Parts Included]

- Truss head screw M4×28 (SUS)

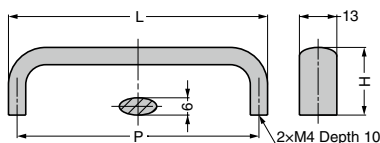

RoHS	CAD	Item Code	Item Name	Material	Finish	L	H	P	Weight (g)	Box (pcs)	Carton (pcs)
		100-011-102	DL-70S	Stainless Steel (SUS303)	Satin	70	23	64	44	20	200
		100-011-101	DL-70M		Polished	70	23	64	44	20	200
		100-011-104	DL-90S		Satin	90	23.5	84	55	20	200
		100-011-103	DL-90M		Polished	90	23.5	84	55	20	200
		100-011-106	DL-110S		Satin	110	24	104	65	15	150
		100-011-105	DL-110M		Polished	110	24	104	65	15	150
		100-011-108	DL-130S		Satin	130	24.5	124	75	15	150
		100-011-107	DL-130M		Polished	130	24.5	124	75	15	150
		100-011-110	DL-150S		Satin	150	25	144	86	15	150
		100-011-109	DL-150M		Polished	150	25	144	86	15	150