

LARGE RECESSED PULL HH-M

SUS



- Large type allows for easy handling with glove on.
- Handlebar does not protrude from the face of the handle.
- All stainless steel pull with handlebar length 200mm and 400mm.

[Applications]

- Special vehicles, containers, large doors and ships, etc.


[Remarks]

- Load capacity represents the strength of the pull itself. Actual load capacity may vary depending on wall and cabinet materials. Please install the pull at places with sufficient strength or places reinforced.



[Parts Included]

- Truss head screw M6×16 (SUS)
- Nut M6 (SUS)

[Application Example]

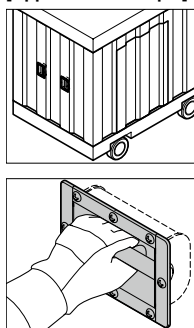

[Cut Out Dimensions]

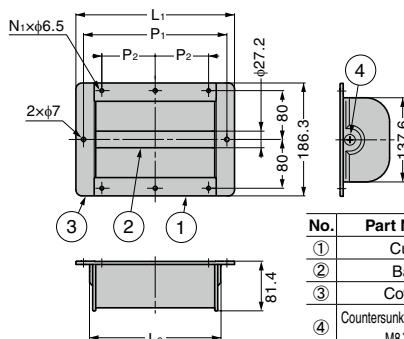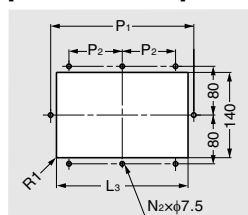


No.	Part Name	Material	Finish
①	Cup	Stainless Steel (SUS304)	Polished
②	Bar	Stainless Steel (SCS13)	
③	Cover	Stainless Steel (SCS13)	
④	Countersunk Head Screw M6×15	Stainless Steel	—

※SCS13 is equivalent to SUS304.

RoHS	CAD	Item Code	Item Name	L1	L2	L3	P1	P2	N1	Holes N2	Load Capacity N	Load Capacity kgf	Weight (kg)	Box (pcs)	Carton (pcs)
✓	3D	100-012-306	HH-M200	260	215	218	235	87.5	6	8	4500	459	2.6	1	4
✓	3D	100-012-305	HH-M400	460	415	418	435	125	8	10	2200	224	3.7	1	2

STAINLESS STEEL RECESSED PULL HH

NSF SUS


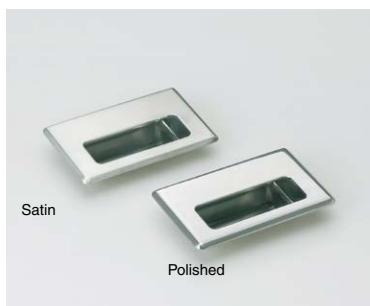


- Simple design.
- Satin and polished finish available.
- HH-FB-1, HH-FC-1, HH-FB-1M and HH-FC-1M are compliant with SEMI standard (SEMI S8-0308).

[Parts Included]

- Only for M4 bolt type: Hexagon nut M4 (SUS), washer 4, spring washer 4

 [Cut Out Dimensions]

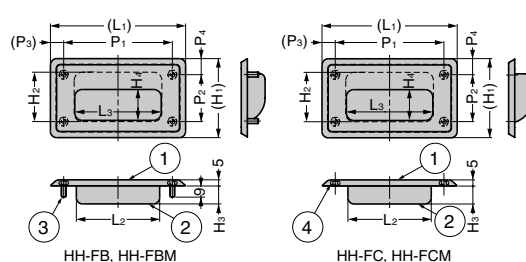

No.	Part Name	Material	Finish
①	Front Plate	Stainless Steel (SUS304)	Satin, Polished
②	Back Cover		Barrel Polished
③	Hexagon Head Bolt M4×10		Plain
④	Hexagon Nut M4		

RoHS	CAD	Item Code	Item Name	Bolt/Nut	Material	Finish	L1	L2	L3	L4	H1	H2	H3	H4	H5	P1	P2	P3	P4	Weight (g)	Box (pcs)	Carton (pcs)
		100-010-090	HH-FB-1	M4 Bolt	Stainless Steel (SUS304)	Satin	138	96	95	99	88	62	21	35	64	110	65	14	11.5	170	10	50
		100-010-091	HH-FC-1	M4 Nut			109.5	71	70	73	64	40	14.5	25	42	88	38	10.75	13	100	10	50
		100-010-092	HH-FB-2	M4 Bolt			109.5	71	70	73	64	40	14.5	25	42	88	38	10.75	13	100	10	100
		100-010-093	HH-FC-2	M4 Nut			109.5	71	70	73	64	40	14.5	25	42	88	38	10.75	13	100	10	100
		100-010-094	HH-FB-3	M4 Bolt			94	61	60	63	60	43	12	45	76	32	9	14	80	10	100	
		100-010-095	HH-FC-3	M4 Nut			94	61	60	63	60	43	12	45	76	32	9	14	80	10	100	
		100-012-104	HH-FB-1M	M4 Bolt		Polished	138	96	95	99	88	62	21	35	64	110	65	14	11.5	170	10	50
		100-012-105	HH-FC-1M	M4 Nut			109.5	71	70	73	64	40	14.5	25	42	88	38	10.75	13	100	10	50
		100-012-106	HH-FB-2M	M4 Bolt			109.5	71	70	73	64	40	14.5	25	42	88	38	10.75	13	100	10	100
		100-012-107	HH-FC-2M	M4 Nut			109.5	71	70	73	64	40	14.5	25	42	88	38	10.75	13	100	10	100
		100-012-108	HH-FB-3M	M4 Bolt			94	61	60	63	60	43	12	45	76	32	9	14	80	10	100	
		100-012-109	HH-FC-3M	M4 Nut			94	61	60	63	60	43	12	45	76	32	9	14	80	10	100	