

STAINLESS STEEL KNOB RSS




- Hollow and light.

[Applications]

- Medical/professional sinks, cars, and ships, etc.

[Parts Included]

- RSS-25S, RSS-25M, RSS-30S, RSS-30M: Truss head screw M4×30 (SUS)
- RSS-38S, RSS-38M, RSS-50S, RSS-50M: Truss head screw M5×30 (SUS)

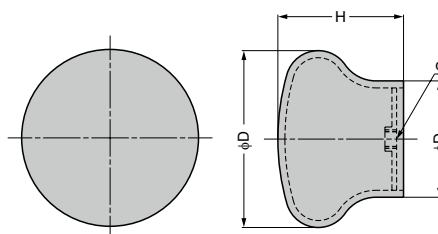

LARGE HANDLES

HANDLES (FRONT SCREW MOUNT)

HANDLES (BACK SCREW MOUNT)


RECESSED PULLS

PULLS & KNOBS

LATCH HANDLES

RoHS	CAD	Item Code	Item Name	Material	Finish	H	D	D ₁	d	Weight (g)	Box (pcs)	Carton (pcs)
✓	3D	100-011-194	RSS-25S	Stainless Steel (SUS304)	Satin	22	25	18	M4	8.5	20	200
✓	3D	100-011-190	RSS-25M		Polished	22	25	18			20	200
✓	3D	100-011-195	RSS-30S		Satin	23	30	20		11	20	200
✓	3D	100-011-191	RSS-30M		Polished	23	30	20			20	200
✓	3D	100-011-196	RSS-38S		Satin	27	38	25	M5	16	20	200
✓	3D	100-011-192	RSS-38M		Polished	27	38	25			20	200
✓	3D	100-011-197	RSS-50S		Satin	34	50	35		30	20	200
✓	3D	100-011-193	RSS-50M		Polished	34	50	35			20	200

KNOB MRB

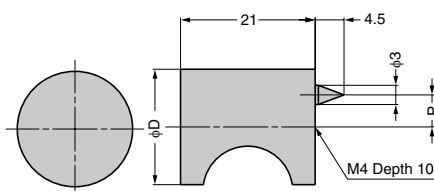

[Remarks]


- Pin position and size may vary.

[Parts Included]

- Truss head screw M4×25

RoHS	CAD	Item Code	Item Name	Material	Finish	D	P	Weight (g)	Box (pcs)	Carton (pcs)
—	3D	100-010-721	MRB-18	Brass	White Bronze Plating	18	5	38	30	300
—	3D	100-010-722	MRB-24			24	5.5	70	30	300

KNOB GLA

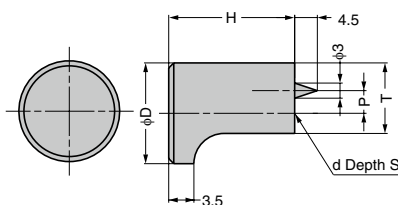

[Remarks]

- Pin position and size may vary.

[Parts Included]

- GLA-12: Truss head screw M3×25
- GLA-16, GLA-20: Truss head screw M4×25

RoHS	CAD	Item Code	Item Name	Material	Finish	D	H	T	P	d	S	Weight (g)	Box (pcs)	Carton (pcs)
—	3D	100-010-718	GLA-12	Brass	White Bronze Plating	12	18	8.5	3.5	M3	8	14	50	500
—	3D	100-012-323	GLA-16			16	22	11	4			29	40	400
—	3D	100-010-720	GLA-20			20	25	14	4.5	M4		52	40	400