


KNOB SGL

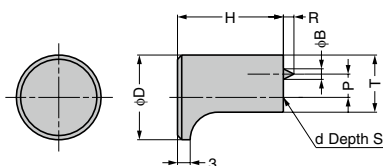

- Uses flame retardant material rated UL94HB.

[Remarks]

- Pin position and size may vary.


[Parts Included]

- SGL-12: Truss head screw M3×28
- SGL-16, SGL-20: Truss head screw M4×28

RoHS	CAD	Item Code	Item Name	Material	Finish	D	H	T	P	B	R	d	S	Weight (g)	Box (pcs)	Carton (pcs)
✓	3D	100-012-016	SGL-12	ABS	Satin Chrome	12	18	8.5	3	2	2	M3	9.5	1	60	1800
✓	3D	100-012-017	SGL-16			16	22	11	4		2.5	M4	13.5	2	40	1200
✓	3D	100-012-018	SGL-20			20	25	13.5	5	2.5			15.5	3.5	30	900

STAINLESS STEEL PULL SD

SUS

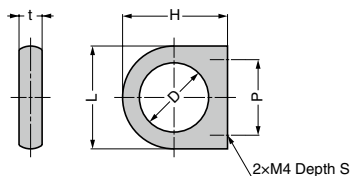

[Parts Included]

- Truss head screw M4×25

RoHS	CAD	Item Code	Item Name	Material	Finish	L	H	t	D	P	S	Weight (g)	Box (pcs)	Carton (pcs)
✓	3D	100-015-022	SD-24S	Stainless Steel (SCS13)	Satin	24.5	25	5.5	16.5	18	5	10	80	800
✓	3D	100-015-023	SD-24M		Polished								80	800
✓	3D	100-015-020	SD-30S		Satin	30.5	31.5	6.5	20.5	21	6	22	50	500
✓	3D	100-015-021	SD-30M		Polished								50	500

*SCS13 is equivalent to SUS304.

KNOB MKZ




[Remarks]

- Pin position and size may vary.

[Parts Included]

- Truss head screw M4×25

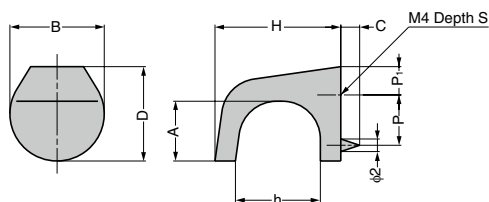

RoHS	CAD	Item Code	Item Name	Material	Finish	D	A	B	C	H	h	P	P1	S	Weight (g)	Box (pcs)	Carton (pcs)
✓	3D	100-018-042	MKZ-15PB	Zinc Alloy (ZDC)	Brass/Clear	16	8	15	2	20	13.5	8	5.5	6	11	50	500
✓	3D	100-018-043	MKZ-15CR		Chrome											50	500
—	3D	100-018-044	MKZ-15BNI		Black Nickel											50	500
✓	3D	100-018-045	MKZ-15WB		White Bronze Plating											50	500
✓	3D	100-018-046	MKZ-15SB		Satin Gold	21	12.5	20	3	26	17	12	4.5	7	29	50	500
✓	3D	100-018-047	MKZ-21PB		Brass/Clear											50	500
✓	3D	100-018-048	MKZ-21CR		Chrome											50	500
✓	3D	100-018-049	MKZ-21BNI		Black Nickel											50	500
✓	3D	100-018-050	MKZ-21WB		White Bronze Plating											50	500
✓	3D	100-018-051	MKZ-21SB		Satin Gold											50	500