


HOOK KB-H

TEST
METHOD 4

SUS

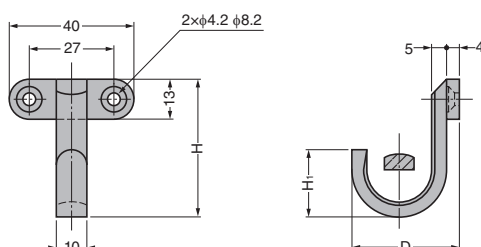

[Parts Included]


- Raised countersunk head tapping screw 4×20 (SUS)

RoHS	CAD	Item Code	Item Name	Material	Finish	D	H	H ₁	Load Capacity N	Load Capacity kgf	Weight (g)	Box (pcs)	Carton (pcs)
		110-029-076	KB-H-35	Stainless Steel	Polished	35	45	22	340	35	49	10	—
		110-029-077	KB-H-40	(SUS303)		40	50	25	280	29	48	10	—

HOOK TA3

TEST
METHOD 4

SUS

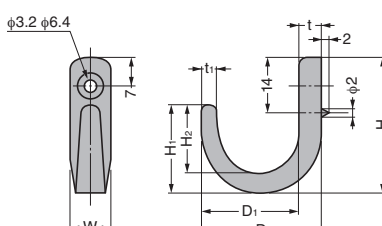

[Parts Included]

- TA3S : Raised countersunk head wood screw 3.1×16 (SUS)
- TA3L : Raised countersunk head wood screw 3.1×16 (SUS)

RoHS	CAD	Item Code	Item Name	Material	Finish	D	D ₁	W	H	H ₁	H ₂	t	t ₁	Load Capacity N	Load Capacity kgf	Weight (g)	Box (pcs)	Carton (pcs)
		110-026-008	TA3S	Stainless Steel	Polished	22	15	9	29	16	12.2	4	3	180	18	10	30	600
		110-026-009	TA3L	(SUS13)		30	20.5	10	34	22	17	5.5	4			19	20	400


*SCS13 is equivalent to SUS304.

HOOK EP

NSF

TEST
METHOD 4

SUS

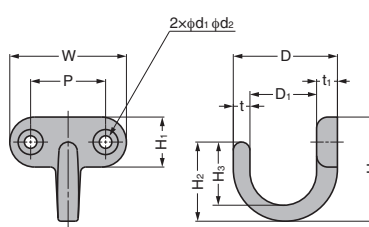

[Parts Included]

- EP-25: Raised countersunk head wood screw 2.7×16 (SUS)
- EP-40: Raised countersunk head wood screw 3.8×20 (SUS)

RoHS	CAD	Item Code	Item Name	Material	Finish	D	D ₁	W	H	H ₁	H ₂	H ₃	t	t ₁	P	d ₁	d ₂	Load Capacity N	Load Capacity kgf	Weight (g)	Box (pcs)	Carton (pcs)
		110-026-000	EP-25	Stainless Steel	Polished	25	16	28	25	12	19	14.5	5	4	18	3	6	240	24	16	30	300
		110-026-001	EP-40	(SUS13)		32	21	36	33	16	25	19.5	6	5	23	4	8			31	20	200


*SCS13 is equivalent to SUS304.

HOOK EL

NSF

TEST
METHOD 4

SUS

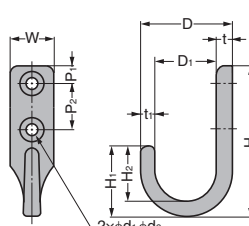

[Parts Included]

- EL-25: Raised countersunk head wood screw 2.7×16 (SUS)
- EL-30: Raised countersunk head wood screw 3.8×20 (SUS)

RoHS	CAD	Item Code	Item Name	Material	Finish	D	D ₁	W	H	H ₁	H ₂	t	t ₁	P ₁	P ₂	d ₁	d ₂	Load Capacity N	Load Capacity kgf	Weight (g)	Box (pcs)	Carton (pcs)
		110-026-004	EL-25	Stainless Steel	Polished	26	16.5	12	40	19	14.5	5.5	4	5	12	3	6	240	24	19	30	300
		110-026-005	EL-30	(SUS13)		32	21	15	54.5	25	19.5	6	5	6	16	4	8			32	20	200

*SCS13 is equivalent to SUS304.