

LARGE UTILITY HOOK XL-CUJ

TEST
METHOD 4


SUS



- Finish: Combination of Polished and satin.
- Large hook XL-CUF 1 with the same combination finish also available.

[Parts Included]

- XL-CUJ45TT : Raised countersunk head tapping screw 3.5×20 (SUS)
- XL-CUJ70TT : Raised countersunk head tapping screw 4×20 (SUS)

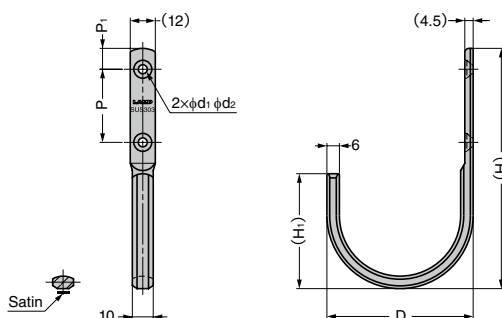RECESSED
HOOKSLATCH
HOOKSSWING
HOOKSSMALL
HOOKSLARGE
HOOKSPANEL
HANGERBRACKETS
&
SHELVING
SYSTEMS

RoHS	CAD	Item Code	Item Name	Material	Finish	D	H	H ₁	P	P ₁	d ₁	d ₂	Load Capacity N	Load Capacity kgf	Weight (g)	Box (pcs)	Carton (pcs)
✓	3D	110-020-012	XL-CUJ45TT	Stainless Steel (SUS303)	Polished/	46	75	36	20	8.5	3.8	7.2	200	20	54	20	120
✓	3D	110-020-013	XL-CUJ70TT		Satin	72	112	56	35	10	4.3	8.6	138	14	84	10	60

Refer to 1 : P.741

LARGE UTILITY HOOK XL-CUF

TEST
METHOD 4


SUS




- Easy to hang big items.
- Finish: Combination of Polished and satin.
- Small hook XL-CUJ 1 with the same combination finish also available.

[Parts Included]

- XL-CUF110TT: Raised countersunk head tapping screw 5×30 (SUS)
- XL-CUF170TT: Raised countersunk head tapping screw 6×30 (SUS)

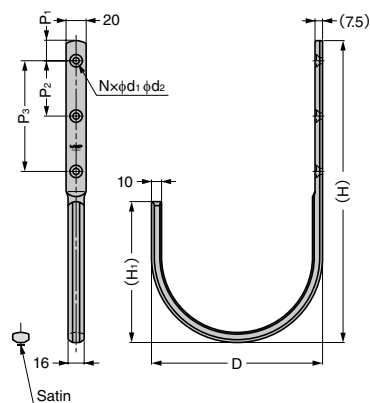

[Application Example]

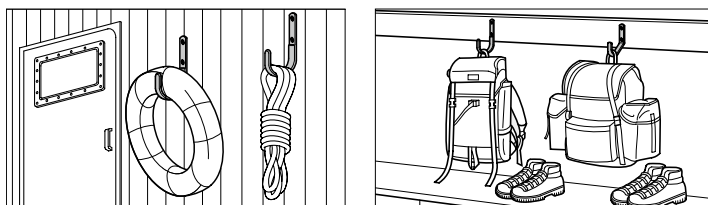

RoHS	CAD	Item Code	Item Name	Material	Finish	D	H	H ₁	P ₁	P ₂	P ₃	N	d ₁	d ₂	Load Capacity N	Load Capacity kgf	Weight (g)	Box (pcs)	Carton (pcs)
		110-020-014	XL-CUF110TT	Stainless Steel (SUS303)	Polished/	112	198	91	17	—	70	2	5.2	10.5	314	32	362	5	30
		110-020-015	XL-CUF170TT		Satin	173	300	138.5	20	55	110	3	6.2	12.5	147	15	569	5	20

Refer to 1 : P.741