


RECESSED
HOOKSLATCH
HOOKSSWING
HOOKSSMALL
HOOKSLARGE
HOOKSPANEL
HANGERBRACKETS
&
SHELVING
SYSTEMS

LARGE UTILITY HOOK JFT180M, JFT260M For Ceiling Mount

NSF

TEST
METHOD 4

SUS


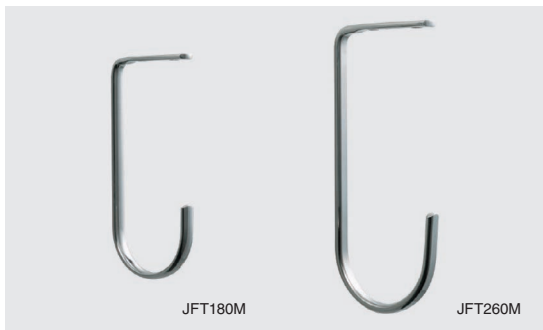


- Easy to hang big items.
- Polished finish.

[Parts Included]

- JFT180M : Raised countersunk head wood screw 4.5×25 (SUS)
- JFT260M : Raised countersunk head wood screw 5.1×38 (SUS)

[Application Example]

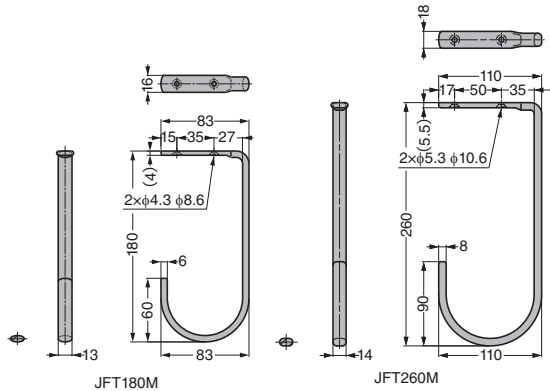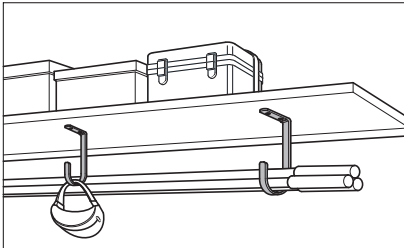

RoHS	CAD	Item Code	Item Name	Material	Finish	Load Capacity N	Load Capacity kgf	Weight (g)	Box (pcs)	Carton (pcs)
✓	3D	110-020-080	JFT180M	Stainless Steel (SUS303)	Polished	98	10	180	5	30
✓	3D	110-020-081	JFT260M			147	15	380	5	30

LARGE UTILITY HOOK XL-SB Large Hat Hook

TEST
METHOD 19


SUS



- Chamfered design.

[Parts Included]

- Raised countersunk head tapping screw 5×30 (SUS)

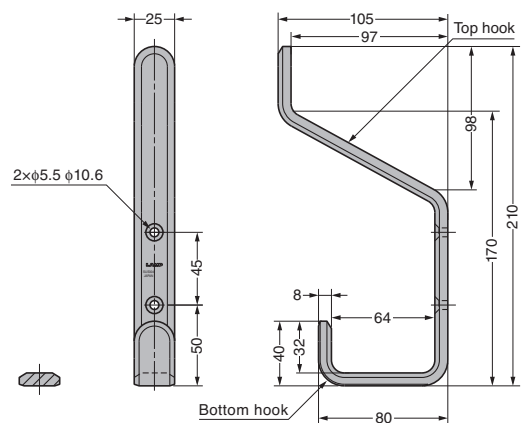

RoHS	CAD	Item Code	Item Name	Material	Finish	Load Capacity				Weight (g)	Box (pcs)	Carton (pcs)
						Top Hook N	Top Hook kgf	Bottom Hook N	Bottom Hook kgf			
✓	3D	110-020-144	XL-SB-210-S	Stainless Steel (SUS304)	Satin finish	200	20	380	39	500	2	12
✓	3D	110-020-145	XL-SB-210-M		Polished	200	20	380	39	500	2	12