

MULTI-PURPOSE LID AD-GD With Damper

SUS



[Installation]



- With damper to keep lid from slamming shut.
- Corrosion resistant.
- Small type AD-GD011-HL is newly launched.
- Wide opening.
- Balance weight restores lid to horizontal position.
- AD-GD011-HL is not for plastic bottles, suitable for separation.

Video Link



[Specifications]

- Operating temperature: 0°C~40°C

[Remarks]

- Indoor use only.
- The closing speed varies depending on the operating temperature. For product stored below the freezing point, leave it indoor above 0°C for several hours before use.

BEARINGS

SWIVELS

MULTI-PURPOSE LIDS

VENTILATORS

MULTI-PURPOSE CAPS

GROMMETS

CABLE GROMMETS



GASKET

BELT REEL PARTITION



GLASS POINT FIX

OTHERS


LED LIGHTS

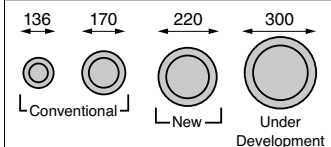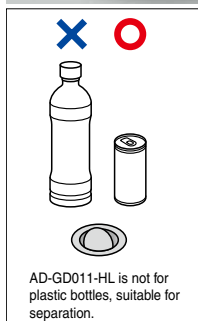


[Flange]

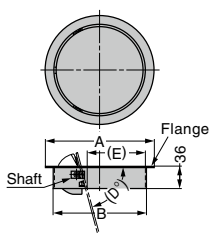 

[Installation]

 

[Cut Out Dimensions]

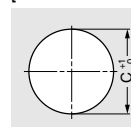

RoHS	CAD	Item Code	Item Name	Material	Finish	A	B	C	D	E	Weight (g)	Box (pcs)	Carton (pcs)
✓	3D	210-029-219	AD-GD011-HL	Stainless Steel (SUS304)	Satin	136	106	107	87	62	460	1	10
✓	3D	210-022-107	AD-GD015-HL			170	146	147	75	90	1000	1	10
✓	3D	210-041-472	AD-GD020-HL			220	196	198	80	128	1060	1	6


MULTI-PURPOSE LID AD-DH015-HL

SUS





- 360° rotation.
- Corrosion resistant.
- Balance weight restores lid to horizontal position.


[Installation]

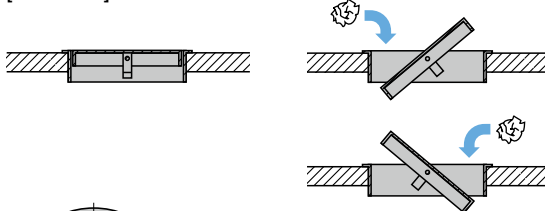

[Flange]

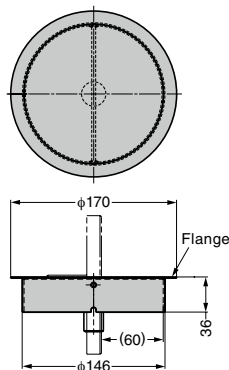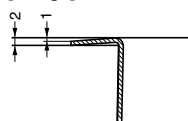

[Cut Out Dimensions]

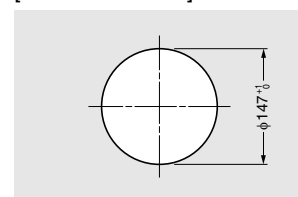

RoHS	CAD	Item Code	Item Name	Material	Finish	Weight (g)	Box (pcs)	Carton (pcs)
✓	3D	210-170-079	AD-DH015-HL	Stainless Steel (SUS304)	Satin	560	1	10