

ALUMINIUM VENTILATOR APK-K



Made of aluminium alloy.

- Smart and simple design.
- Small holes ($\phi 1.5$ mm) prevents insects from entering.
- APK-K160 and APK-K210: When used with optional frame 1, ventilator can be removed for cleaning.


[Remarks]

- Please use glue for installation.



[Sold Separately]

- Frame APK-KF226P 1

[Application Example]

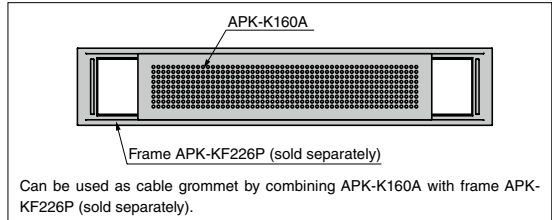

[Cut Out Dimensions]

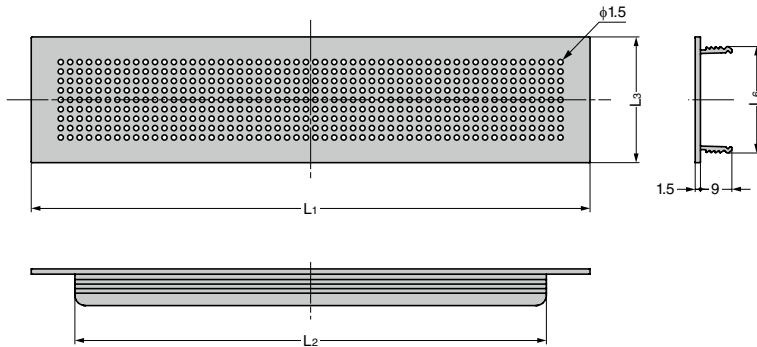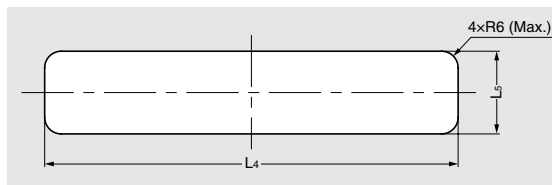

RoHS	CAD	Item Code	Item Name	Colour	Material	Max. Exhaust Area mm ²	L1	L2	L3	L4	L5	L6	Weight (g)	Box (pcs)	Carton (pcs)				
✓	3D	210-032-545	APK-K160A-SL	Anodised Silver	Aluminium Alloy	859	160	135	150	30.5	30.5	27	30	180					
✓	3D	210-032-544	APK-K160A-BL	Black Anodised									30	180					
✓	3D	210-032-547	APK-K210A-SL	Anodised Silver									30	180					
✓	3D	210-032-546	APK-K210A-BL	Black Anodised		1145	212	187	200	30.5	30.5	37	30	180					
✓	3D	210-034-399	APK-K400A-SL	Anodised Silver									20	80					
✓	3D	210-034-400	APK-K400A-BL	Black Anodised									20	80					
✓	3D	210-034-401	APK-K400A-DBR	Dark Brown Anodised		3958	400	375	60	50 ^{+0.5} ₀	50	95	20	80					
✓	3D	210-034-402	APK-K400A-WT	White Electrodeposition									20	80					
✓	3D	210-034-403	APK-K400AW-SL	Anodised Silver									20	80					
✓	3D	210-034-404	APK-K400AW-BL	Black Anodised									20	80					
✓	3D	210-034-405	APK-K400AW-DBR	Dark Brown Anodised									5938	80	70 ^{+0.5} ₀	70	130	20	80
✓	3D	210-034-406	APK-K400AW-WT	White Electrodeposition														20	80

Refer to 1 : P.995

BEARINGS

SWIVELS

MULTI-PURPOSE LIDS

VENTILATORS

MULTI-PURPOSE CAPS

GROMMETS

CABLE GROMMETS

GASKET

BELT REEL PARTITION

GLASS POINT FIX

OTHERS

LED LIGHTS