


CORNER CAP AS-C For Single-groove

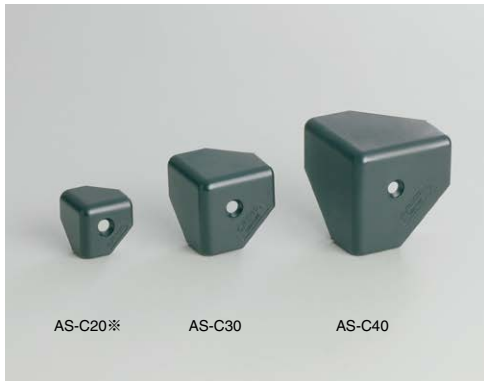

AS-C20※

AS-C30


AS-C40

- Rounded plastic corner cap prevents from injuring or scratching and beautifies the corner of aluminium frame.
- Easy to install with only one position to be tightened with screw.
- Glue or double-sided tape can also be used for fixation.

[Remarks]

- Do not use on corners of a door.

[Application Example]

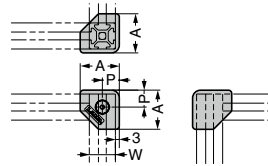

[Corner Cap AS-C]

RoHS	CAD	Item Code	Item Name	Aluminium Frame	A	P	W	Material	Colour	Weight (g)	Box (pcs)	Carton (pcs)
CE	3D	210-040-680	AS-C20	20×20 Groove Width 6 mm	30	13	20	PA	Black	6	200	1600
CE	3D	210-040-681	AS-C30	30×30 Groove Width 8 mm	43	18	30			14	50	400
CE	3D	210-040-682	AS-C40	40×40 Groove Width 8 mm, 40×40 Groove Width 10 mm	58	23	40			29	25	200

MULTI-PURPOSE CAP KD




- One-touch installation.
- Can be used on sheet metal and wooden board, ideal for cable grommet.
- KD-380-350B can also be used for holes of concealed hinge.

[Specifications]

- Uses flame retardant material rated UL94V-2.

[Cut Out Dimensions]

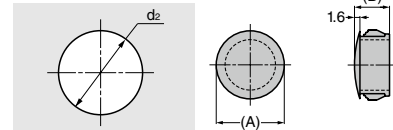

RoHS	CAD	Item Code	Item Name	Material	Colour	A	B	D ₁	d ₂	Board Thickness	Pack(pcs)	Box (pack)	Carton (pcs)
CE	3D	120-038-140	KD-80-64B-P20	PA	Black	8	8	6.1	6.4	1.6	20	5	—
CE	3D	120-038-141	KD-95-80B-P20			9.5		7.7	8		20	5	—
CE	3D	120-038-124	KD-120-95B-P20			12		9.3	9.5		20	5	—
CE	3D	120-038-125	KD-135-110B-P20			13.5		10.9	11		20	5	—
CE	3D	120-038-126	KD-146-127B-P20			14.6		12.5	12.7		20	5	—
CE	3D	120-038-127	KD-167-143B-P20			16.7		14.1	14.3		20	5	—
CE	3D	120-038-128	KD-182-159B-P20			18.2		15.8	15.9		20	5	—
CE	3D	120-038-129	KD-200-175B-P20			20		17.3	17.5		20	5	—
CE	3D	120-038-131	KD-232-190B-P20			23.2	10.3	18.9	19	0.8-3.2	20	5	—
CE	3D	120-038-130	KD-226-206B-P20			22.6		20.4	20.6		20	5	—
CE	3D	120-038-132	KD-258-222B-P20			25.8		22	22.2		20	5	—
CE	3D	120-038-133	KD-305-255B-P20			30.5		25.3	25.5		20	5	—
CE	3D	120-038-134	KD-310-280B-P20			31		27.6	28		20	5	—
CE	3D	120-038-135	KD-333-301B-P20			33.3		30	30.1		20	5	—
CE	3D	120-038-136	KD-349-320B-P20			34.9		31.8	32		20	5	—
CE	3D	120-038-137	KD-380-350B-P20			38	11.5	34.9	35		20	5	—
CE	3D	120-038-138	KD-427-380B-P20			42.7		37.9	38		20	5	—
CE	3D	120-038-139	KD-484-450B-P20			48.4		44.6	45		20	5	—
CE	3D	120-038-142	KD-550-510B-P20			55		50.6	51		20	5	—