


■スリット

形 HP-SV□□ 形 HP-SH□□ 形 HP-SC01

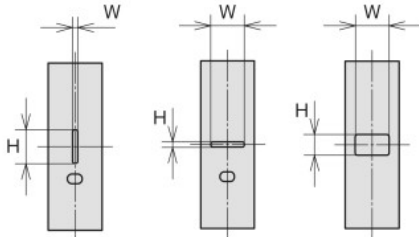



形番	W(幅)mm	H(高さ)mm
HP-SV05	0.5	6.4
HP-SV10	1.0	6.4
HP-SV20	2.0	6.4
HP-SH05	6.4	0.5
HP-SH10	6.4	1.0
HP-SH20	6.4	2.0
HP-SC01	6.4	3.9

■フィルタ

形 HP-U02


偏光方向:縦 偏光方向:横

ばね用ステンレス  
銅板 t0.2

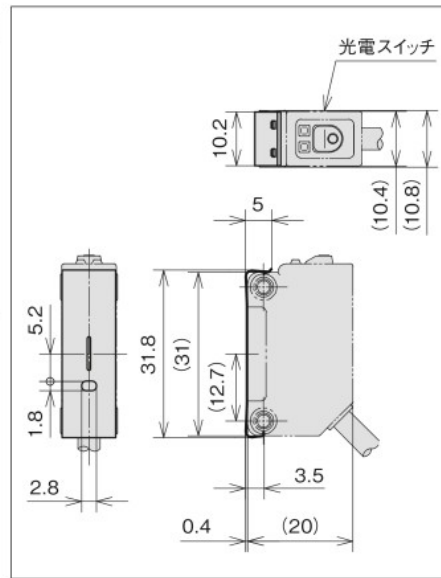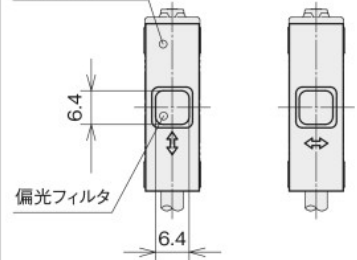


■反射板


形 FE-RR8

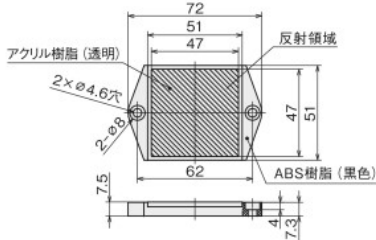


形 FE-RR15

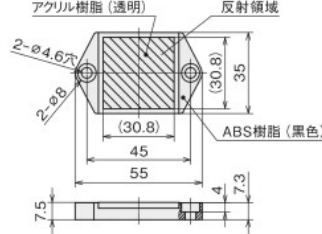


形 FE-RR17

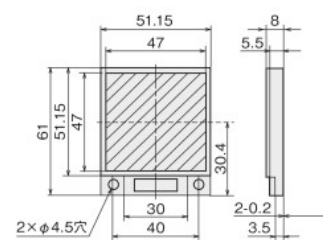


形 FE-RR18

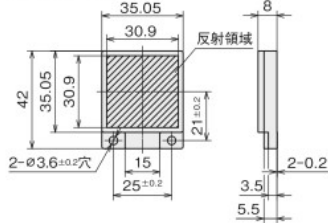


形 FE-RR21

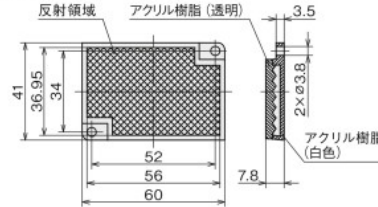


形 FE-RR22

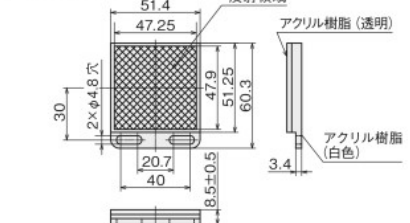


形 FE-RR23

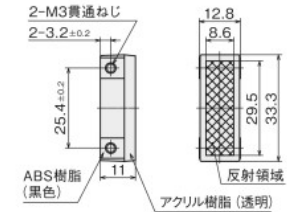


形 FE-RR24

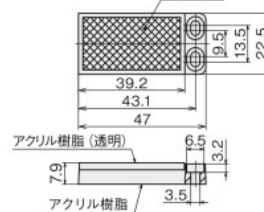


形 FE-RR25

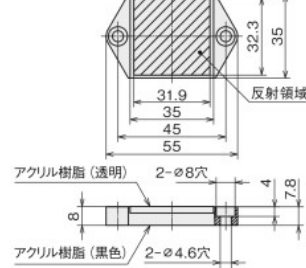

形 FE-RR26

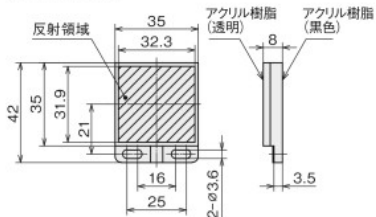

形 FE-RR27 ※取付ねじ部: ステンレス鋼

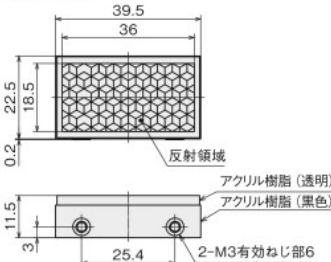

形 FE-RR28 ※形 FE-RR25の金属スリーブ付モデル

